

**SIMPLE FLOW METER**

-STRAIGHT-

■ Application Use to perform simple flow rate check.



## ■ Features

- M-FLM-S-33R-TM is equipped with a simple thermometer.
- The resin part is hexagonal; to hook onto the tool.

■ Material: Polyamide/Brass




Usable temperature (Oil) (°C) 120 or less  
Usable temperature (Water) (°C) 80 or less  
Allowable pressure (MPa) 0.98  
Max. flow rate (l/min) 10

M-FLM-S-33

M-FLM-S-22

M-FLM-S-3R3

M-FLM-S-33R-TM

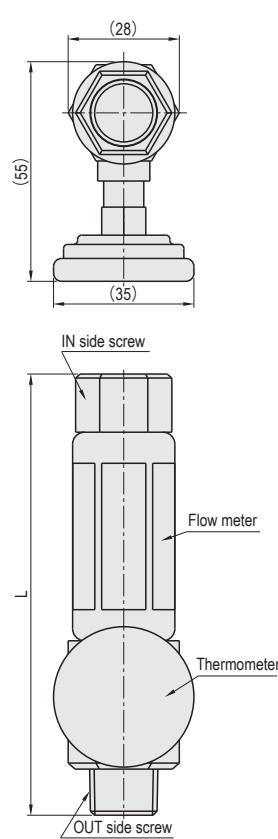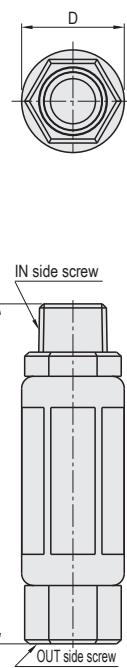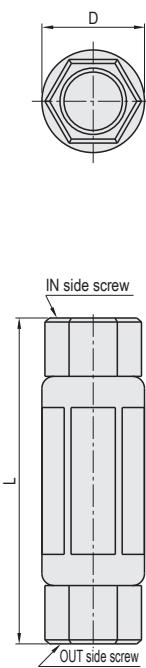

L	D	IN side screw	OUT side screw	Part Number		Unit Price 1~3 pcs
				Type	No.	
81	25.5	RC(PT)1/4	RC(PT)1/4	M-FLM-S	22	
		RC(PT)3/8	RC(PT)3/8		33	
85		R(PT)3/8	R(PT)3/8		3R3	Quotation
110	-	RC(PT)3/8	R(PT)3/8		33R-TM	



Order

Part Number  
**M-FLM-S-22**



Days  
to Ship

**Quotation**



Price

**Quotation**