

NEW
新产品

经济型 调整块

请按照选型步骤①~④选择型式和参数后进行订购。



Order
订货范例

型式(①Type · ②M)

C-LEMNTN8

③A

40

型式(①Type · ②D)

C-FJFNV58

③M


12

④A


70

■全尼龙底座型万向调节脚杯

C-LEMNTN

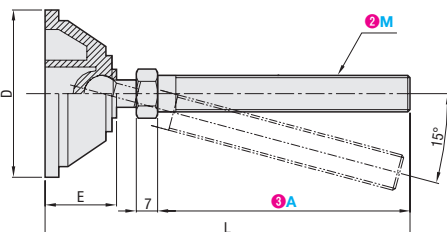


Type	M材质	S表面处理
C-LEMNTN	碳钢	镀锌

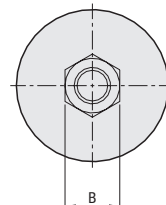


型式		③A	L	D	E	B	垂直负载 (kN)
①Type	②M						
C-LEMNTN	8	40	60	40	15	13	1
		40	60	40	15	13	1
	12	57	80	40	15	13	1
		83	120	55	23.5	13	1.5
	16	50	94	70	25	24	3
		100	144				

■不锈钢重载型防滑固定调节脚杯

C-FJFNV

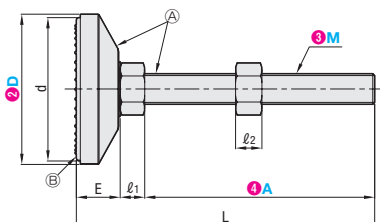

Type	M材质
C-FJFNV	不锈钢/丁腈橡胶

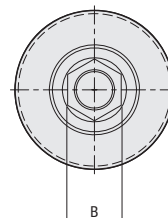

型式		③M	④A	d	L	l1	l2	B	E	垂直负载 (kN)
①Type	②D									
C-FJFNV	58	12	70	50.5	101	10	10	19	20	6
			100		131					
		16	70		104					
			100		134					
	78	12	70	70.5	103	10	10	19	22	10
			100		133					
		16	70		106					
			100		136					
		20	100		139	16	16	30		
			130		169					
	98	16	70	90.5	111	13	13	24	27	12
			100		141					
20		100	144							
		130	174							
24		100	146		18	18	36			
150	196									



Delivery
交货期

请询价 下述2种方法



24小时在线

Web报价



FAX报价

请致电: 021-6710-8701