

NEW
新产品

MISUMI
经济型

精密ロックナット
精密锁紧螺帽

库存品
隔天发货



Order
订货范例

型式




C-RM

R型



CAD 3D

库存

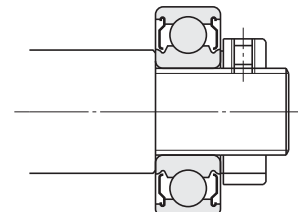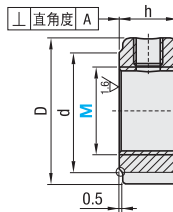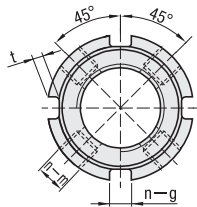

Type	垂直度
C-RM (标准型)	$\perp 0.005 A$

构成零件	材质	硬度	表面处理
主体	SC45	28~32HRC	镀锌酸盐
锁紧销	磷青铜	-	-

螺纹精度
ISO 4H 等级

型式		M × 螺距 (细牙螺纹)	D	h	t	d	n-g-m	最大紧固扭矩 (N · m)
C-RM	8	M8 × 0.75	16	8	1.6	13	4-3-M4	3.5
	10	M10 × 1.0	18			15		
	12	M12 × 1.0	20			17		
	15	M15 × 1.0	25	10	2	21.5	4-4-M5	4.5
	16	M16 × 1.5	28			24		
	17	M17 × 1.0	32			28		
	20	M20 × 1.0	32	12	2	34	4-5-M6	8
	25	M25 × 1.5	38			38		
	27	M27 × 1.5	42			41		
	30	M30 × 1.5	45	14	2.5	48	4-6-M6	18
	33	M33 × 1.5	52			53		
	35	M35 × 1.5	58			60		
	40	M40 × 1.5	65	16	3	65	4-6-M8	18
	45	M45 × 1.5	70			69		
	55	M55 × 2.0	75			74		
	60	M60 × 2.0	80				4-7-M8	

13 轴承座组件



Order
订货范例

型式




C-FM

F型



CAD 3D

库存

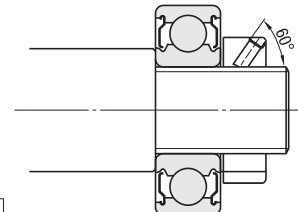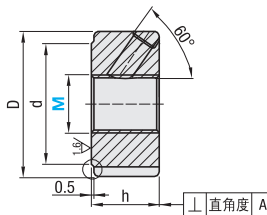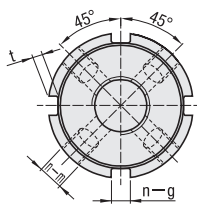

Type	垂直度
C-FM (标准型)	$\perp 0.005 A$

构成零件	材质	硬度	表面处理
主体	SC45	28~32HRC	镀锌酸盐
锁紧销	磷青铜	-	-

螺纹精度
ISO 4H 等级

型式		M × 螺距 (细牙螺纹)	D	h	t	d	n-g-m	最大紧固扭矩 (N · m)
C-FM	12	M12 × 1.5	30	14	2	26	4-4-M5	4.5
	15	M15 × 1.0				28		
	17	M17 × 1.0				32		
	20	M20 × 1.0	38	16	2	34	4-4-M6	8
	20-1	M20 × 1.5				41		
	24	M24 × 1.5				48		
	25	M25 × 1.5	45	18	2.5	53	4-5-M6	18
	30	M30 × 1.5				48		
	35	M35 × 1.5				52		
	40	M40 × 1.5	58	20	3	60	4-6-M8	18
	45	M45 × 1.5	65			65		
	50	M50 × 1.5	70			69		
	55	M55 × 2.0	75	22	3	74	4-7-M8	18
	60	M60 × 2.0	80					

轴承座组件
圆型

轴承座组件
方型

轴承

滚珠轴承组件

小零件
轴承用

滚珠轴承随动器

MISUMI 制胜时间 助力智造



通过WEB迅速检索零件

<https://www.misumi.com.cn> 米思米

检索