


Plastic Hose Mounting Connectors / Arm Locking Couplers

Plastic Hose Mounting Connectors



RoHS

Type	Material							Applicable Hose
	Nipples	Inner	Rubber Caps	Washer	Swaging Sleeve Nut	Rubber Gasket	Sleeve, Ring	
TCSM	SCS13	-	-	-	SCS13	NBR	POM	HOTR□, HOTRS□, HOTSG□, HOTG□

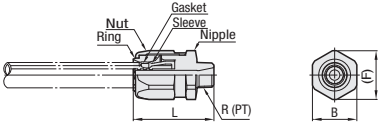

Part Number		L	Hex/Octagon Socket B	V	(F)	G	R (PT)	Applicable Hose	Unit Price 1 ~ 4 pc(s).	Volume Discount Rate 5 ~ 10 pcs.
Type	No.									
TCSM (Stainless Steel)	9	54.5	30	7	33	-	3/8	HOTR□ HOTRS□ HOTSG□ HOTG□		
	12	59	32	10	35.5		1/2			
	15	60	36	12	40		1/2			
	19	64	41	16.5	45		3/4			
	25	70	50	22	54		1			

Operating Pressure is the same as for Applicable Hoses.

For orders larger than indicated quantity, please check with WOS.

Arm Locking Couplers

Male Threaded Adapters



RoHS

Type	Material
SNAMA	SCS14A

Part Number		R (PT)	D	d	H	h	B	Unit Price 1 ~ 19 pc(s).	Volume Discount Rate 20 ~ 30 pcs.
Type	No.								
SNAMA	15A	1/2	32	20	58	26	33		
	20A	3/4	32	20	58	26	33		
	25A	1	37	24	70	32	41		
	40A	1 1/2	53	36	79	40	57		
	50A	2	63	46	87	47	68		

For orders larger than indicated quantity, please check with WOS.

Female Threaded Adapters



RoHS

Type	Material
SNAFA	SCS14A

Part Number		Rc (PT)	D	d	H	h	B	Unit Price 1 ~ 19 pc(s).	Volume Discount Rate 20 ~ 30 pcs.
Type	No.								
SNAFA	15A	1/2	32	20	39	26	33		
	20A	3/4	32	20	39	26	33		
	25A	1	37	24	49	34	41		
	40A	1 1/2	53	36	55	40	57		
	50A	2	63	46	63	47	69		

For orders larger than indicated quantity, please check with WOS.

Hose Mounting Adapters



RoHS

Type	Material
SNAHA	SCS14A

Part Number		D	d	H	h	I	J	Unit Price 1 ~ 19 pc(s).	Volume Discount Rate 20 ~ 30 pcs.
Type	No.								
SNAHA	20A	32	20	90	37	21	33		
	25A	37	23	108	48	27	41		
	40A	53	37	116	53	41	58		
	50A	63	46	134	60	53	70		

For orders larger than indicated quantity, please check with WOS.

Male threaded Sockets



RoHS

Type	Material		
SNAMJ	Main Body	Cam	Ring
	SCS14A	SMS1025	SUS304

Part Number		R (PT)	A	B	C	H	h	Unit Price 1 ~ 19 pc(s).	Volume Discount Rate 20 ~ 30 pcs.
Type	No.								
SNAMJ	15A	1/2	110	52	32	52	32		
	20A	3/4	110	52	32	52	32		
	25A	1	125	60	37	59	38		
	40A	1 1/2	188	90	54	68	44		
	50A	2	197	97	63	76	51		

For orders larger than indicated quantity, please check with WOS.

Female Tapped Sockets



RoHS

Type	Material		
SNAFJ	Main Body	Cam	Ring
	SCS14A	SMS1025	SUS304

Part Number		Rc (PT)	A	B	C	H	h	Unit Price 1 ~ 19 pc(s).	Volume Discount Rate 20 ~ 30 pcs.
Type	No.								
SNAFJ	15A	1/2	110	52	32	51	32		
	20A	3/4	110	52	32	51	32		
	25A	1	125	60	37	60	38		
	40A	1 1/2	188	90	54	69	45		
	50A	2	197	97	63	77	51		

For orders larger than indicated quantity, please check with WOS.

Hose Mounting Sockets



RoHS

Type	Material		
SNAHJ	Main Body	Cam	Ring
	SCS14A	SMS1025	SUS304



Part Number
TCSM25
SNAMA20A

For orders larger than indicated quantity, please check with WOS.

Arm Locking Couplers are manufactured according to the US MIL Standards A-A-59326-1998 (MIL-C-27487-1992 previously), thus compatible with the same size products of the same standards from other manufacturers.

Hose Clamps

Suitable for connecting Duct Hoses on P.1327.

Hose clamp is the product to prevent the hose from falling off. Structurally, clearance may occur at the smallest tightening torque.

Standard




RoHS



Part Number
HOSBS13N

HOSBS

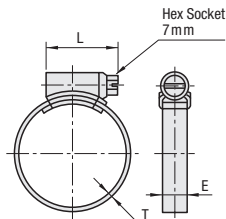

Material: SUS304

Part Number		Hose O.D. Tightening Range (mm)	L	T	E	Tightening Torque (N · m)	Unit Price 1 ~ 9 pc(s).	Volume Discount Rate 10 ~ 50
Type	No.							
HOSBS	9N	9.5~12	19	0.7	9.5	3.5		
	13N	13~20						
	16N	16~22				4.4		
	19N	18~25	24					
	22N	22~30				5.2		
	25N	25~35						
	28N	30~40						
	31N	35~50				6.1		
	38N	40~55						
	44N	45~60	33	0.8	12			
	50N	55~70				6.9		
	60N	60~80						
	70N	70~90						
	83N	85~100						
	95N	90~120						
	104N	100~125						
	127N	130~150						
	146N	130~160				6.1		
	149N	150~180						
	175N	170~200						
	200N	190~230						


For orders larger than indicated quantity, please check with WOS.

Spiral



RoHS

HOSSB

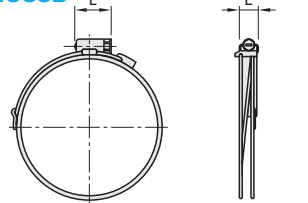

Part Number		Hose O.D. Tightening Range (mm)	L	E	Tightening Torque (N · m)	Unit Price 1 ~ 9 pc(s).	Volume Discount Rate 10 ~ 30
Type	No.						
HOSSB	30	30~37	30.5	15	5		
	32	32~42					
	47	47~57					
	61	61~71					
	71	71~81					
	86	86~96					
	90	90~110					


For orders larger than indicated quantity, please check with WOS.

Hand Tightening



RoHS

HOSBH

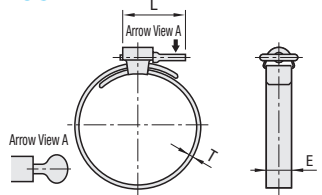

Part Number		Hose O.D. Tightening Range (mm)	L	T	E	Unit Price 1 ~ 9 pc(s).	Volume Discount Rate 10 ~ 30
Type	No.						
HOSBH	15	15~22	32	0.5	12		
	18	18~28					
	20	20~34					
	25	25~40					
	40	40~55					

For orders larger than indicated quantity, please check with WOS.



Part Number
HOSBH18

With Safety Cover



RoHS

Type	Clamp	Housing	Screw	Caps
HOABS (Semi Stainless Steel)	SUS430	SUS430	Steel (Zinc Plating)	PE
HOASU (All Stainless Steel)	SUS304	SUS304	SUS304	PE



Part Number
HOABS13

Part Number		Hose O.D. Tightening Range (mm)	L	T	E	Tightening Torque (N · m)	HOABS		HOASU	
Type	No.						Unit Price 1 ~ 9 pc(s).	Volume Discount Rate 10~30	Unit Price 1 ~ 9 pc(s).	Volume Discount Rate 10~30
HOABS HOASU	8	8~12	21.5	0.7	9	3.5				
	10	10~15								
	11	11~17								
	13	13~20								
	16	16~22								
	18	18~25								
	22	22~30	27	0.8	13	5				
	25	25~35								
	27	27~40								
	30	30~45								
	35	35~50				6				
	40	40~55								
	45	45~60								
	55	55~70								