 



MOLD COUPLERS

-PLUGS-




Matching Joint Plug Connections P.245 Guide for Socket · Plugs P.247 · 248

RoHS 10




LJPSH (Hexagonal head long type) Matching Sockets: P.249

※Socket connection section

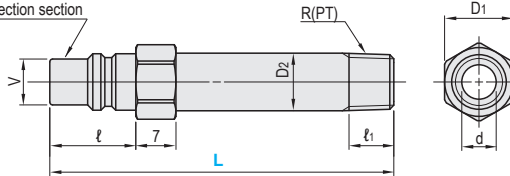


M Brass (C3604)
Thread JIS B0203
Tapered thread for tubing R(PT)

RoHS 10



LJPS (Hexagonal hole long type) Matching Sockets: P.249

※Socket connection section

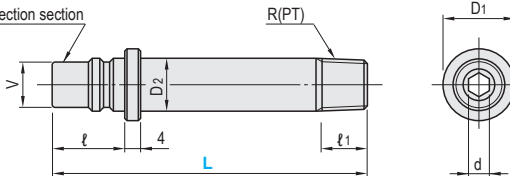

M Brass (C3604)
Thread JIS B0203
Tapered thread for tubing R(PT)


Through hexagonal hole for wrenching on both ends.
The hex-wrench hole extends to a point mid-way from both ends. It is not fully pierced.

Max. pressure MPa (kgf/cm ²)	Matching Sockets	Socket connection parts		D1	D2	d	Tapered thread R(PT)	l ₁	Opposite side Nominal dia.		Part Number		L		
		V	ℓ						Type	No.					
1.0 (10)	Mold Coupler Series Socket hole diameter V=8 Common to all sizes	8	15	12	10	6	1/8	9	6A	1/8	Hexagonale head, long LJPSH (Brass)	1	100 110 120 130 140 150 200		
				14	13.2		1/4	11	8A	1/4	2				
		8	15	14	10	5	1/8	9	6A	1/8	Hexagonale hole, long LJPS (Brass)	1		40~115 (5 mm increments)	120~200 (10 mm increments)
				13.2	1/4		11	8A	1/4	2					

Part Number		Unit Price (1~9 pcs)							
Type	No.	L100	L110	L120	L130	L140	L150	L200	
LJPSH	1								Quotation
	2								


Part Number		Unit Price (1~9 pcs)			
Type	No.	L40~60	L65~100	L105~150	L160~200
LJPS	1				
	2				

RoHS 10



KPH (For hose) Matching Sockets: P.249

※Socket connection section

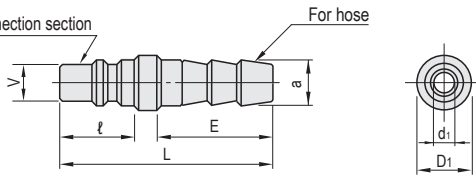

M Brass (C3604)

Max. pressure MPa (kgf/cm ²)	Matching Sockets	Socket connection parts		L	D1	Inner dia. d ₁	For hose		Opposite side Nominal dia.		Part Number		Unit Price 1~9 pcs
		V	ℓ				a	E	Type	No.			
1.0 (10)	Mold Coupler Series Socket hole diameter V=8 Common to all sizes	8	15	42	12	5	8	21	8A	1/4	For hose KPH (Brass)	2	Quotation
					15	6	12	21	10A	3/8	3		

Matching Sockets: MISUMI's mold coupler KSH · KTSH · KSM · KISM · KFF · KTF · F120-KSH · F120-KSM · F120-KFF · F120-KSHL · F120-KTSHBL P.249
Nitto's mold couplers K□□SH (E.g. K02SH) · K□□TSH · K□□ISM (E.g. K02ISM) · K□□ISM · K□□SF · K□□TSF · K□□SHL



Part Number	L
LJPSH 2	100
LJPS 2	100
KPH 2	



Quotation



Quotation