

NEW

SUCTION CUP


SUCTION CUP (SPONGE TYPE)

■ Suction Cup (Sponge type)




VC-NS


No.8

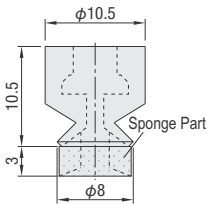


No.12

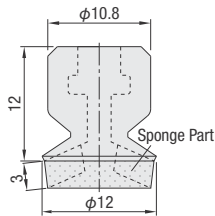


No.15

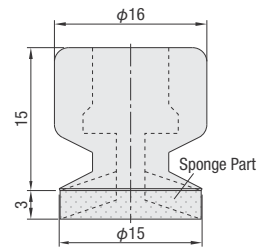


No.20

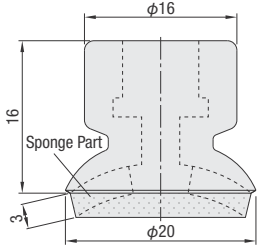

No.30

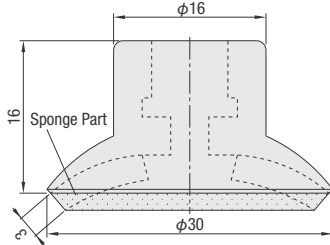

No.40

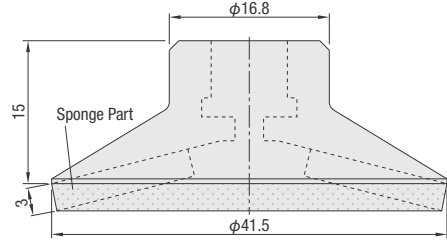

Body: Silicone
 Sponge: Single layered silicone
 Shore A50~70
 Specification Temperature -70°C~200°C
 Maximum Operating Temperature 120°C

Applicable metal fittings	Mounting type	Cup dia.	Weight (g) ^{*1}	Part Number		Unit Price
				Type	No.	1~30 pcs
VC-KNG7 VC-KNGB7	Embedded type	8	1	VC-NS (Flat)	8	Quotation
		12	1		12	
15		3	15			
20		4	20			
30		4	30			
41.5		8	40			
VC-KNG11 VC-KNGB11						

*1 The weight is an approximate value which serves only as a guideline.



Order

Part Number
VC-NS12



Days to Ship

Quotation



Price

Quotation

REMOVAL RELATED PRODUCTS