

LOCATING PILOT PINS


SLPS・SDST・SDKL were discontinued in 2017.

Male thread type

RoHS



SLTL (Fixed P dimension)
SLTLH (Configurable P and B dimensions)

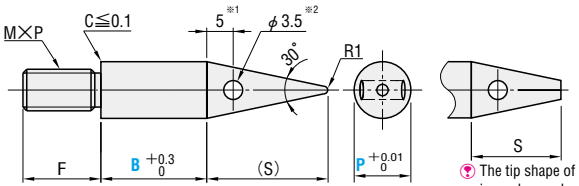

For SLTLH, (S) $\approx 1.6 \times P$. ≈ 1 SLTL6・SLTLH8 $\rightarrow 2$ ≈ 2 SLTL6・SLTLH8 $\rightarrow 2.5$

SKS93
37 ~ 43HRC


M×P	F	S	Catalog No. Type	P	B	Base unit price 1~9 pieces	M×P	F	Catalog No. Type	No.	P 0.01mm increments	B 1mm increments	Base unit price 1~9 pieces
5×0.8	12	10	(Fixed P dimension) SLTL	6	5 10	Quotation	5×0.8	12	(Configurable P and B dimensions) SLTLH	8	6.00~8.00	5~50	Quotation
6×1.0				8			6×1.0			10	8.00~10.00		
8×1.25				9			8×1.25			12	10.00~12.00		
10×1.5	15	15		10	10 15		10×1.5	15		14	12.00~14.00		
12×1.75		17		12			12×1.75			16	14.00~16.00		
16×2.0	25	20		14	15 20		16×2.0	25		20	16.00~20.00		

Inlay male thread type

RoHS



SLPS (Fixed P dimension)
SLPSH (Configurable P, B, and T dimensions)

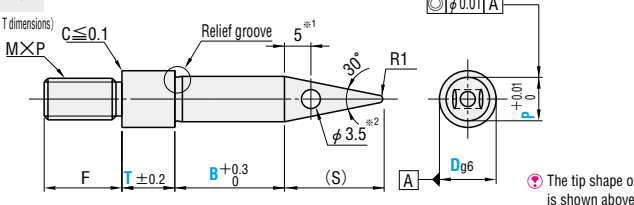

For (s), $s \approx 1.6 \times P$. ≈ 1 D8 $\rightarrow 2$ ≈ 2 D8 $\rightarrow 2.5$

SKS93
37 ~ 43HRC

M×P	F	P	B	T	S	Catalog No. Type	D	Base unit price 1~9 pieces	M×P	F	Catalog No. Type	D	P 0.01mm increments	B 1mm increments	T 1mm increments	Base unit price 1~9 pieces
6×1.0	12	6	3	10		(Fixed P dimension) SLPS	8	Quotation	6×1.0	12	(Configurable P, B, and T dimensions) SLPSH	8	6.00~8.00	5~60	3~15	Quotation
8×1.25		8	5	15			10		8×1.25			10	8.00~10.00			
12×1.75	15	10		17			13		12×1.75	15		13	10.00~12.00			
16×2.0		16	10	20			16		16×2.0			16	12.00~14.00			
		20		25			20			25		20	14.00~16.00			
							25					25	16.00~20.00			

Order

Catalog No. — P — B — T

SLTL 8 — B10

SLTLH 14 — P13.80 — B20

SLPSH 16 — P14.00 — B60 — T15

Days to Ship

Quotation


Price


Quotation

Alterations

Catalog No. — P — B — T — (SC)

 SLPSH 10 — P8.50 — B10 — T3 — SC9

Alteration	Code	Spec.	1Code
	SC	Tip taper length change 8<SC<S 1mm increments	Quotation

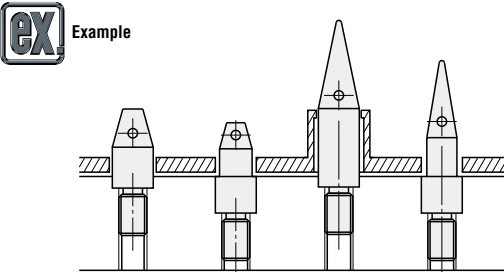


Female thread type

RoHS



SNST (Fixed P dimension)
SNSTH (Configurable P and B dimensions)

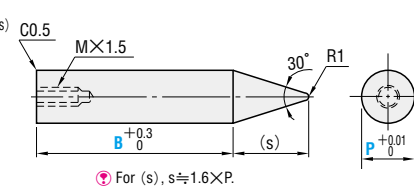

For (s), $s \approx 1.6 \times P$.

SKS3
60 ~ 63HRC


M×P	Catalog No. Type	P	B	Base unit price 1~9 pieces	M×P	Catalog No. Type	No.	P 0.01mm increments	B 0.1mm increments	Base unit price 1~9 pieces
4×0.7	(Fixed P dimension) SNST	6	10 15	Quotation	4×0.7	(Configurable P and B dimensions) SNSTH	6	6.00~7.00	10.0~80.0	Quotation
5×0.8		8			5×0.8		8	7.00~8.00		
		10	15 20		6×1.0		10	8.01~10.00		
		12			6×1.0		12	10.00~12.00		
6×1.0		13	20 30		6×1.0		13	12.01~13.00		
		15			6×1.0		15	13.01~15.00		
		16	30 40		8×1.25		16	15.01~16.00		
8×1.25		20	40 50		8×1.25		20	16.00~20.00		

Small head female thread type

RoHS



SDST (Fixed P dimension)
SDSTH (Configurable P and B dimensions)

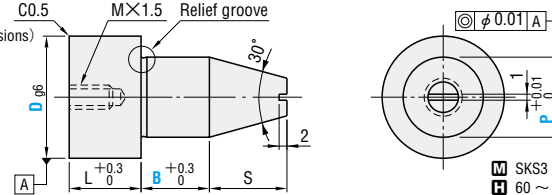

Details of undercut

SKS3
60 ~ 63HRC


D _{g6}	M×P	P	L	S	B	Catalog No. Type	D	Base unit price 1~9 pieces	D _{g6}	M×P	L	S	Catalog No. Type	D	P 0.01mm increments	B 0.1mm increments	Base unit price 1~9 pieces
8	-0.005	5×0.8	6	15	6	(Fixed P dimension) SDST	8	Quotation	8	-0.005	5×0.8	6	(Configurable P and B dimensions) SDSTH	8	6.00~7.00	3.0~20.0	Quotation
10	-0.014	6×1.0	8		8		10		10	-0.014	6×1.0	8		10	7.00~9.00	3.0~30.0	
13	-0.006	8×1.25	10	20	12		13		13	-0.006	8×1.25	10		13	9.00~12.00		
16	-0.017	10×1.5	12		17		16		16	-0.017	10×1.5	12		16	12.00~15.00	3.0~50.0	
20	-0.007	12×1.75	16	24	20		20		20	-0.007	12×1.75	16		20	15.00~18.00		
	-0.020				15					-0.020							

Small head one-side flat type

RoHS



SDKL (Fixed P dimension)
SDKLH (Configurable P and B dimensions)

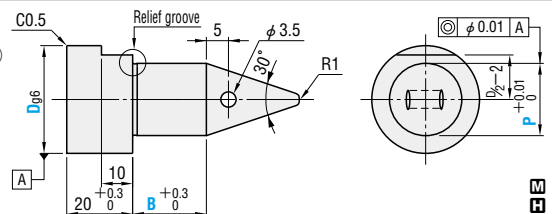

Details of undercut

SKS3
60 ~ 63HRC


D _{g6}	P	B	Catalog No. Type	D	Base unit price 1~9 pieces	D _{g6}	Catalog No. Type	D	P 0.01mm increments	B 0.1mm increments	Base unit price 1~9 pieces
10	-0.005	6	(Fixed P dimension) SDKL	10	Quotation	13	(Configurable P and B dimensions) SDKLH	13	7.00~9.00	3.0~30.0	Quotation
13	-0.014	8		13		16		16	9.00~12.00		
16	-0.017	10		16		20		20	12.00~15.00	3.0~50.0	
20	-0.007	12		20		25		25	15.00~20.00		
25	-0.020	16		25							

Order

Catalog No. — P — B

SNST 8 — B10

SDSTH 13 — P11.48 — B28.0

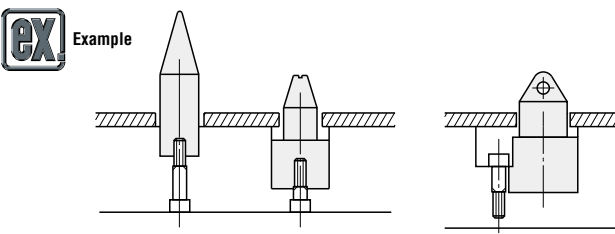

Days to Ship

Quotation

Price

Quotation